



LADDER

ACCESSORIES





Table of Contents

Product	Page
• ToolLasso® System	1
• JobBucket	2
• Pail Shelves and Project Trays	2-3
• Stepladder Hanger	3
• Extension Ladder Stabilizers	4-5
• Ladder Levelers	5-6
• Misc. Extension Ladder Accessories	7
• Other Accessories	8
• Ladder Jacks	9



ToolLasso® System



- Compatible with select Werner products. Visit wernerladder.com for details
- Secure tools from falling to protect your investment
- Puts tools in easy reach
- Available with belt clip
- Bulk option available



25lbs.
Load
Capacity

TL2BC-20

- 2 clip strips of 10 cards each
- Each card includes belt clip and 2 ToolLassos®



TL2BC-12

- 12 cards in case cut display box
- Each card includes belt clip and 2 ToolLassos®



TL50

- 50 ToolLasso® bungees in a box



TL5-20

- 2 clip strips of 10 cards each
- Each card includes 5 ToolLassos®



TL5-12

- 12 cards in a cut case
- Each card includes 5 ToolLassos®



Stepladder**Accessories**

*Job***Bucket**

AC50-JB-5



25lbs.
Load Capacity

- Compatible with select Werner products. Visit wernerladder.com for details
- Increases the work space on your ladder
- Sturdy lug and socket feature for seamless installation
- Heavy duty handle
- Rugged professional grade construction
- Over 600 cubic inch capacity
- Shipped in boxes of 5

PK76-3 Universal Auto Closing Pail Shelf



- Works with Werner fiberglass stepladders and aluminum 400 Series stepladders
- Spill-Proof®; rugged molded plastic construction
- Easy to keep clean
- Automatically closes with stepladder
- Built-in rag rack
- 4 per carton. Includes mounting hardware and instructions

PK76-9 Universal Pail Shelf



- Works with Werner fiberglass stepladders and aluminum 400 Series ladders
- Two piece with aluminum arms
- Spill-Proof®; rugged molded plastic construction
- Built-in rag rack
- 6 per carton. Includes mounting hardware and instructions

AC24 Multipurpose Project Tray



25lbs.
Load Capacity


- Conveniently holds tools, paints and other supplies
- Attaches easily
- Works at multiple heights
- Fits MT Series, M1 Series, Type IA stepladders and Type IAA stepladders

76-2 Molded Plastic Pail Shelf



- For 6000 and 6200 Series
- Spill-Proof®; rugged construction
- Easy to keep clean
- Automatically closes with stepladder
- Includes mounting hardware and instructions

AC11 Stepladder Hanger

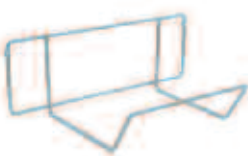

- Mounts to wall to hold stepladders
- Industrial strength, coated steel wire construction
- 6 per carton

Extension Ladder**Accessories**

AC78 QuickClick™ Stabilizer



- 44" span and 10" stand-off allow working around windows, gutters and overhangs
- Spring-loaded locking latch makes it easier and quicker to install/remove than any other stabilizer on the market
- Mar-resistant rubber end caps protect work surface
- Paint can hook and instructions included
- No tools required

AC96 Aluminum Stabilizer




- 47" span and 10" stand-off allow working around windows, gutters and overhangs
- Works with Werner aluminum extension ladders with rails up to 3" x 1-3/16", and all duty ratings
- Attaches in minutes
- Mar-resistant rubber end caps protect work surface
- Paint can hook, mounting hardware and instructions included

AC36-2 Stabilizer End Caps



- End covers for the AC78 and AC96 stabilizers
- Protects work surface
- 6 pair per carton

97P Adjustable True Grip® Stabilizer

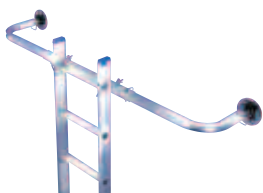

- Span adjustment: 49", 57", 65"
- Stand-off distance: 12" or 29-1/2"
- Rectangular stabilizer spans double windows
- Quickly converts stand-off distance for larger overhangs
- Includes rubber pads, fleece bonnets, mounting hardware and instructions
- Fits rails up to 3" x 1-3/16"
- Mounts quickly and easily

PK80-2 Level-Master® Automatic Levelers



- Easily attaches to Werner fiberglass and aluminum extension ladders to level ladder on uneven surfaces
- Levels and automatically locks securely in place
- Adjusts up to 8-1/2"
- Plated steel swivel shoe
- Width of ladder is increased by approximately 3-3/4" (The ladder's duty rating will remain the same after proper installation of leveler)
- Two (2) ladder levelers are included with mounting hardware and instructions

Extension Ladder**Accessories**

PK70-1 LeveLok® Leveler and Base Units



LeveLok® is a registered trademark of the LeveLok® Corporation.

- Includes one (1) LeveLok® Ladder Leveler with two (2) base attachments
- Base units stay attached to the ladder while leveler can be easily removed when not in use
- Swivel shoe with ice pick on both ends
- Leveler can be used on either side of ladder
- Adjusts up to 8-1/2"

PK70-2 LeveLok® Base Units



LeveLok® is a registered trademark of the LeveLok® Corporation.

- Includes two (2) LeveLok® Ladder Leveler base attachments
- Base units attach to the ladder and are used with LeveLok® Ladder Leveler supplied in PK70-1 and PK70-3

PK70-3 LeveLok® Ladder Leveler



LeveLok® is a registered trademark of the LeveLok® Corporation.

- Includes one (1) LeveLok® Ladder Leveler
- Attaches to base units supplied with PK70-1 and PK70-2

71**Padded Fixed V-Rung**

- Slip-resistant rubber grip attached to steel v-rung for wood, metal or concrete poles
- Pre-pierced holes in fiberglass top rails are provided to accept this accessory
- Includes mounting hardware and instructions

AC19-2 Extension Ladder Covers

- Helps prevent damage to support surfaces
- Designed to “snap” over extension ladder rail end caps
- Resists paints, stains, thinners and solvents
- One (1) pair of covers per package; 6 packages per carton

AC20 Paint Can Hook

- Includes two (2) hooks with can openers
- Holds one gallon can
- Steel 3/16" diameter
- Two (2) per package; 12 packages per carton

AC22 Paint Can/Bucket Hanger

- Holds one gallon can
- Easy on and off attachment
- Right or left hand use
- Plated steel
- 6 packages per carton

Other**Accessories**

ARB10-10 Adjustable Roof Bracket



- Adjusts to common roof pitches (10/12-40°, 14/12-50°, 21/12-60°)
- Holds standard 2" x 10" plank
- Multiple nail slots for easy installation and removal
- Durable powder-coated steel

FRB4510-10 Fixed Roof Bracket



- For use on roofs with 12/12 pitch (45°)
- Holds standard 2 x 10 plank
- Durable powder-coated steel

AC18MT MT Series Standing Platform



- 300 lb. load capacity, Type IA duty rating
- Slip-resistant surface
- Kicks out of way for easy climbing
- Lightweight aluminum

LadderJacks



- One pair of ladder jacks for use on two extension ladders to hold a stage
- Increases productivity and working comfort
- Mounts to either side of extension ladder
- Designed for quick field adjustments
- Patented platform clamping system
- Lightweight, sturdy and easy to use
- Recommended for use with 300 lb. Type IA and 375 lb. Type IAA extension ladders. OSHA and ANSI allow use with 250 lb. Type I extension ladders also.

AC10-14-02 Ladder Jack



- 2 rung, short body model
- Accepts stages up to 14" wide

AC10-20-02 Ladder Jack



- 2 rung, long body model
- Accepts stages up to 20" wide

AC10-20-03 Ladder Jack



- 3 rung, long body model
- Accepts stages up to 20" wide